


CAT. NO.....:	292-3320		292-4520		297-3320		297-4520	
PORE SIZE (um).....:	0.2		0.2		0.2		0.2	
UPPER CAP. (mL).....:	1000		1000		1000		1000	
BOTTLE NECK SIZE.....:	33mm		45mm		33mm		45mm	
MEMBRANE COLOR.....:	WHITE		WHITE		WHITE		WHITE	
MEMBRANE DIA (mm)....:	90		90		90		90	
	INCHES	MM	INCHES	MM	INCHES	MM	INCHES	MM
A (UPPER I.D.).....:	4.49	114.0	4.49	114.0	4.49	114.0	4.49	114.0
B HEIGHT.....:	6.43	163.3	6.50	165.1	6.43	163.3	6.50	165.1
C DIA (BASE).....:	1.39	35.3	1.89	48.0	1.39	35.3	1.89	48.0
D DIM.....:	2.48	63.0	3.00	76.2	2.48	63.0	3.00	76.2
NOM. WT. (gms).....:	117		118		117		118	

MATERIALS		
CATALOG NUMBER	292-3320/-4520	297-3320/-4520
UPPER CONTAINER	PS	PS
COVER	PS	PS
COLLAR	YELLOW PS	BLUE PS
ADAPTOR	WHITE LOPE	WHITE LOPE
GASKET	FOAMED LOPE	FOAMED LOPE
MEMBRANE	SFCA	PES
VENT PLUG	CA	CA

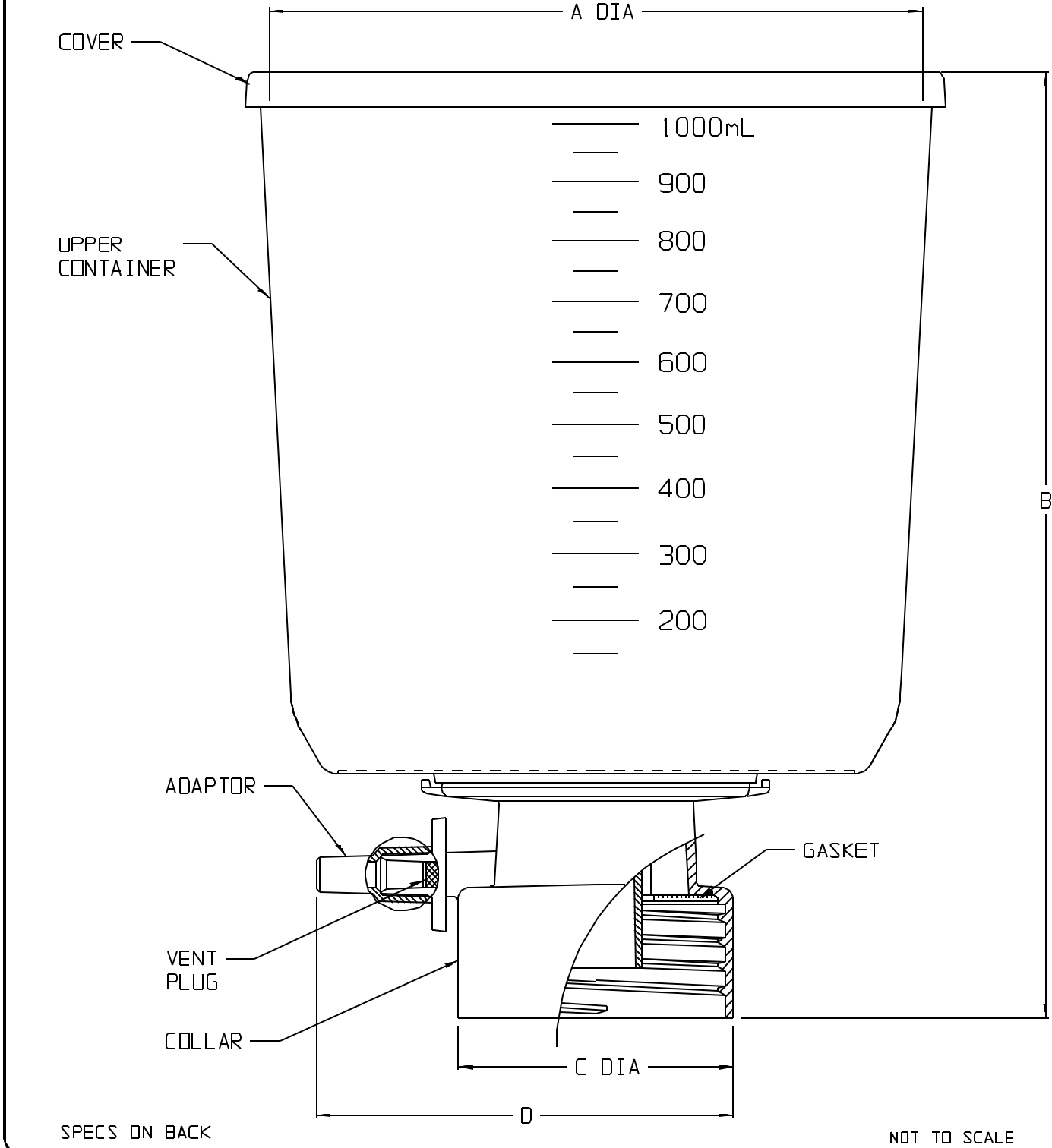

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	MC ²	APP'D	PSS 00-029X-XX20	REV.
CK'D				0902
DESCRIPTION:				
BOTTLE TOP FILTERS				