


CATALOG NO.....		002003-0004
MAT'LS.	BOTTLE....	LDPE
	CLOSURE....	PP
SIZE (NOM VOL mL/oz):		125/4
NOM. BRIM CAP. (mL):		140
NECK FINISH (mm):		24-415
THREAD (T.P.I.):		8
NOM. WEIGHT W/CLOSURE (gms):		20
		INCHMM
A (NECK I.D.):		0.69 ±0.0217.5 ±0.5
B (HT. W/CLOSURE):		3.97 ±0.08100.8 ±2.0
C (HT. W/O CLOSURE):		3.88 ±0.0898.6 ±2.0
D (DIA):		1.98 ±0.0650.3 ±1.5
F (HEIGHT):		0.12 ±.023.0 ±0.5
G (HEIGHT):		2.71 ±.0668.8 ±1.5
W.T.(NOM. WALL THK):		0.0401.02

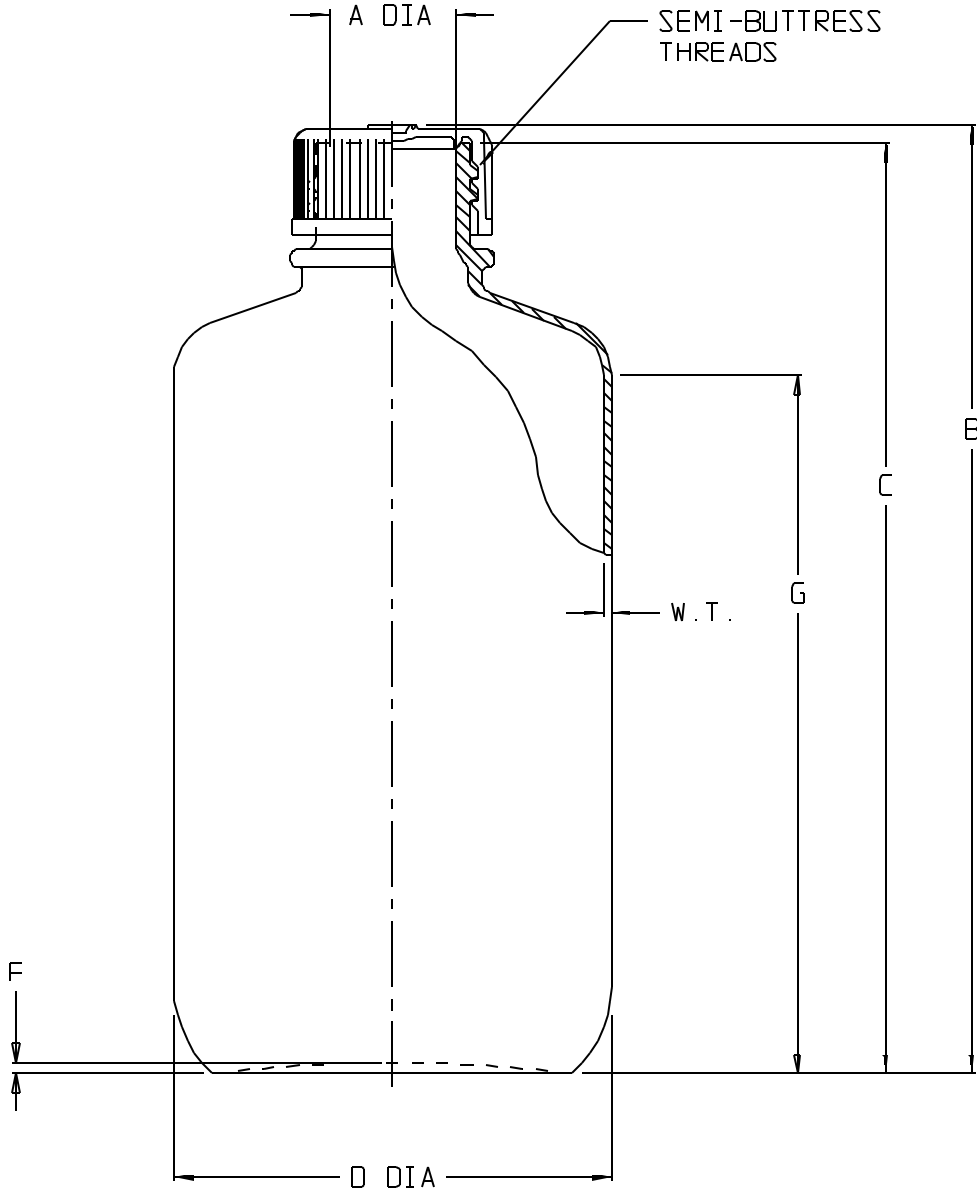

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	MCC	APP'D	PVC	PSS 00-2003-0004-S	REV. -
CK'D	PVC		6/10/93		
DESCRIPTION:				ROUND NARROW MOUTH LAB QUALITY BOTTLE	