


CATALOG NO.	NOMINAL CAPACITY (mL)				MATERIALS	
					BOTTLE	CLOSURE
002115	500	1000	2000	3000	PPCO	WHITE PP

SIZE CODE.....:	-500		-1000		-2000		-3000	
SIZE (NOM VOL mL/oz)	500/16		1,000/32		2,000/64		3,000/96	
NOM. BRIM CAP. (mL):	600		1120		2220		3450	
NECK FINISH (mm)....:	70		70		70		70	
THREAD (T.P.I.).....:	4		4		4		4	
NOM. WEIGHT W/CLOSURE (gms).....:	85		125		160		260	
	INCHES	MM	INCHES	MM	INCHES	MM	INCHES	MM
A (BTLE. NECK I.D.):	2.40 ±.05	61.0±1.3	2.40 ±.05	61.0±1.3	2.40 ±.05	61.0±1.3	2.40 ±.05	61.0±1.3
B (HT. W/CLOSURE)...	6.92 ±.09	175.8±2.3	8.38 ±.10	212.9±2.5	9.62 ±.12	244.4±3.0	9.70 ±.12	246.4±3.0
C (HT. W/O CLOSURE):	6.50 ±.09	165.1±2.3	7.93 ±.10	201.4±2.5	9.18 ±.12	233.2±3.0	9.30 ±.12	236.2±3.0
D (DIA).....:	2.91 ±.08	73.9±2.0	3.65 ±.08	92.7±2.0	4.76 ±.09	120.9±2.3	6.13 ±.10	155.7±2.5
W.T.(NOM. WALL THK):	0.070	1.78	0.075	1.91	0.085	2.16	0.095	2.41

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

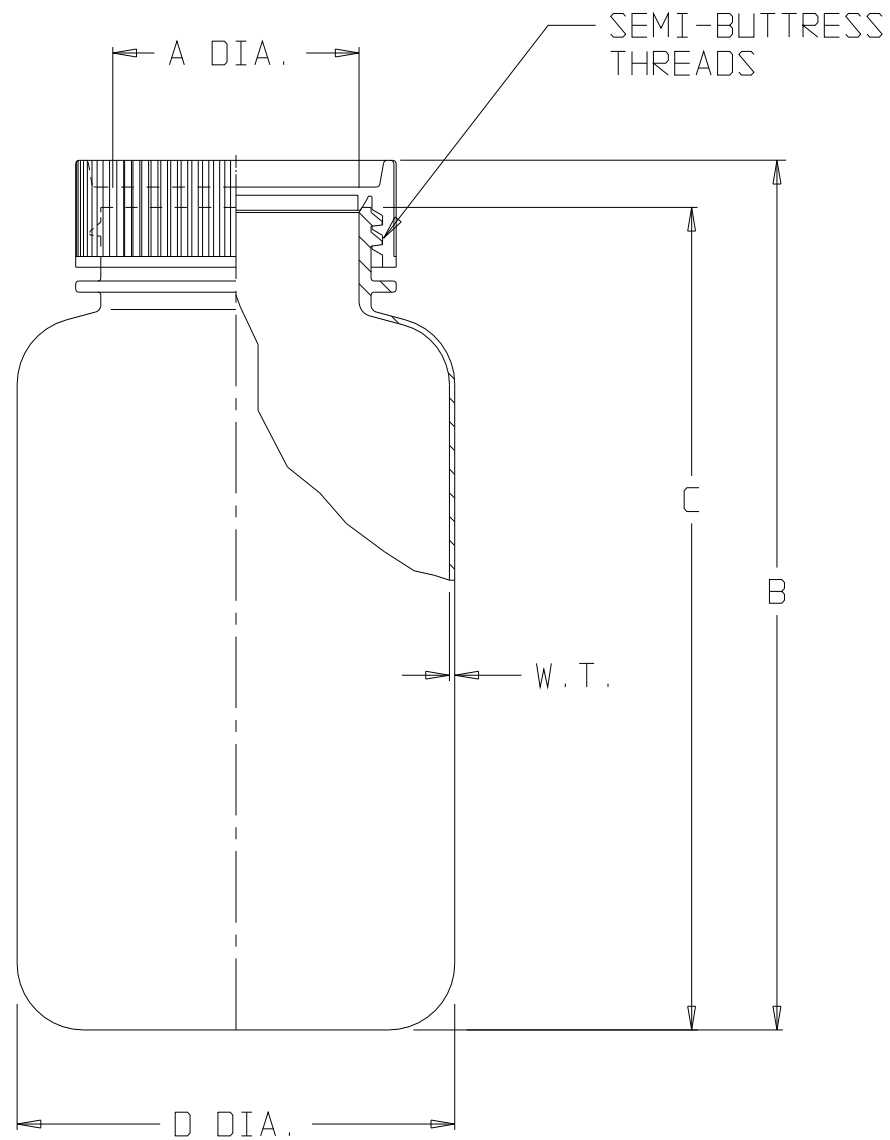

NOT TO SCALE

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	TL	APP'D	PSS 00-2115-XXXX-1	REV. 0212
CK'D	PB	GRP 2/29/12		

DESCRIPTION:

MASON JARS