


CATALOG NO.	MATERIAL	
	FITTING	O-RING
002159	ACETAL	BLUNA-N

SIZE CODE.....:	0001	
NOM. WEIGHT (gms)....:	2	
HOSE BARB SIZE.....:	1/4"	
	INCH	MM
D (DIA).....:	.62 ±0.03	15.7 ±0.8
H (HEIGHT).....:	1.36 ±0.03	34.5 ±0.8
F (DIA).....:	.18 ±0.03	4.6 ±0.8

SIZE CODE.....:	0002	
NOM. WEIGHT (gms)....:	2	
HOSE BARB SIZE.....:	3/8"	
	INCH	MM
D (DIA).....:	.62 ±0.03	15.7 ±0.8
H (HEIGHT).....:	1.36 ±0.03	34.5 ±0.8
F (DIA).....:	.25 ±0.03	6.4 ±0.8

NOTES:

- ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
- THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

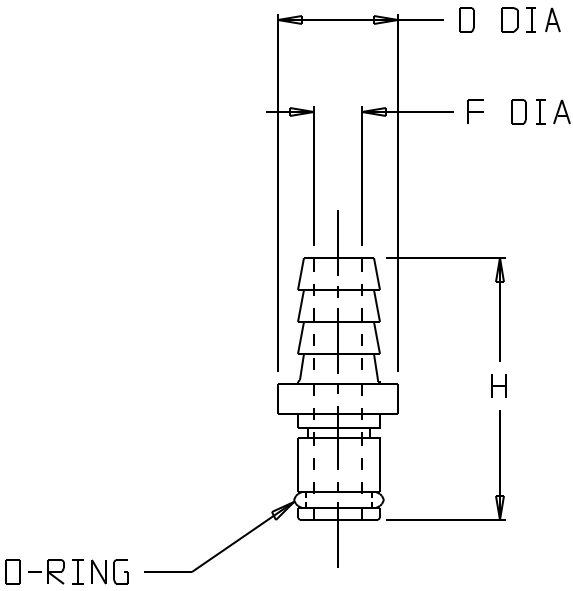

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher SCIENTIFIC		Thermo Fisher Scientific 75 Panorama Creek Drive Rochester, NY 14625-2385, USA		
MADE	MC ²	APP'D	PVC	REV.
CK'D	BB		2/10/00	02/00
DESCRIPTION:		QUICK DISCONNECT INSERT 1/4" & 3/8" HOSE BARB		

PSS 00-2159-000X-1