


CATALOG NO.	NOMINAL CAPACITY (oz)			MATERIALS			
				BOTTLE	CLOSURE	SPOUT	VENT
002436	8	16	32	LOPE	*PP	LOPE	PTFE

* BLEACH BOTTLES (-0256/-0506/-1006)
HAVE AN HOPE CLOSURE

SIZE CODE.....:	-025X		-050X		-100X	
SIZE (NOM VOL mL/oz):	250/8		500/16		1000/32	
NOM. BRIM CAP. (mL):	290		580		1140	
NECK FINISH (mm)....:	38-415		38-415		38-415	
THREAD (T.P.I.).....:	6		6		6	
NOM. WEIGHT W/CLOSURE (gns).....:	45		58		100	
	INCH	MM	INCH	MM	INCH	MM
A (NECK I.D.).....:	1.16 ±0.03	29.5 ±0.8	1.16 ±0.03	29.5 ±0.8	1.16 ±0.03	29.5 ±0.8
B (HT. W/CLOSURE)....:	5.42 ±0.08	137.7 ±2.0	6.81 ±0.09	173.0 ±2.3	8.25 ±0.10	209.6 ±2.5
C (HT. W/O CLOSURE):	5.31 ±0.08	134.9 ±2.0	6.69 ±0.09	170.0 ±2.3	8.08 ±0.10	205.2 ±2.5
D (DIA).....:	2.46 ±0.07	62.5 ±1.8	3.02 ±0.08	76.7 ±2.0	3.80 ±0.08	96.5 ±2.0
W.T.(NOM. WALL THK):	0.030	0.8	0.040	1.0	0.050	1.3

CATALOG NUMBER	CHEMICAL	CLOSURE COLOR
-0251 -0501 -1001	ACETONE	RED
-0252 -0502 -1002	ETHYL ALCOHOL	WHITE
-0253 -0503 -1003	METHANOL	GREEN
-0254 -0504 -1004	ISOPROPANOL	YELLOW
-0255 -0505 -1005	DISTILLED WATER	NATURAL
-0256 -0506 -1006	BLEACH	WHITE

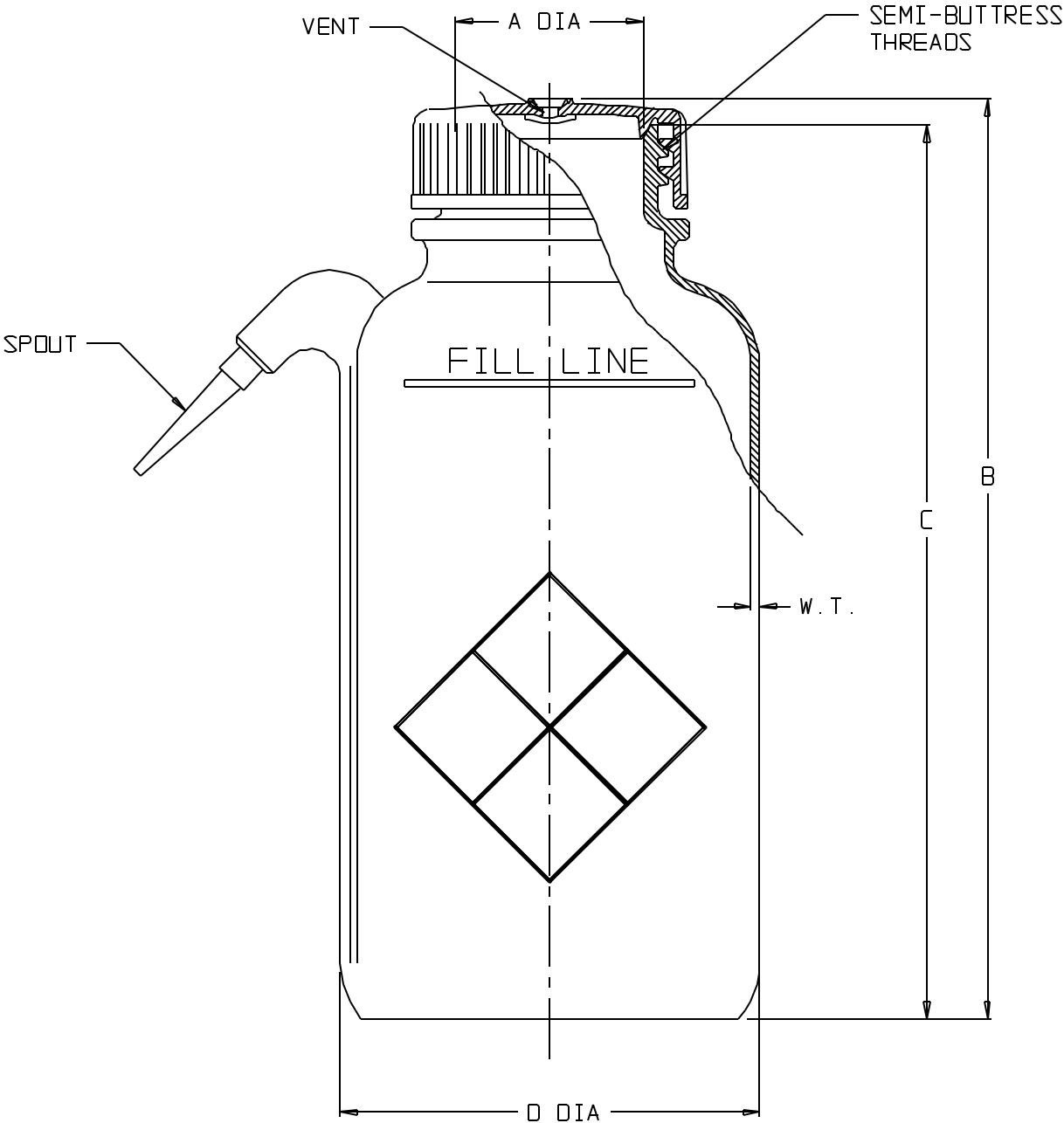

SPECS ON BACK

NOT TO SCALE

NOTES:

- ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
- THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	MC ²	APP'D	PVC	PSS 00-2436-XXXX-1	REV.
CK'D	PVC		8/24/99		0899
DESCRIPTION: UNITARY VENTED RIGHT-TO-KNOW WASH BOTTLES					