


CATALOG NUMBER.....	4105-2800	
MATERIAL.....	PC	
BRIM CAPACITY (mL).....	3050	
NOMINAL WEIGHT (gms).....	390	
	INCHES	MM
A (NECK I.D.).....	2.23 ±0.04	56.6 ±1.0
B (NECK O.D. W/ LIP).....	2.87 ±0.04	72.9 ±1.0
C (NECK O.D. BELOW LIP)...	2.69 ±0.04	68.3 ±1.0
D (OVERALL O.D.).....	8.0 ±0.1	203 ±2.5
H (HEIGHT).....	9.0 ±0.1	229 ±2.5
W.T. (WALL THICKNESS).....	0.14	3.6

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

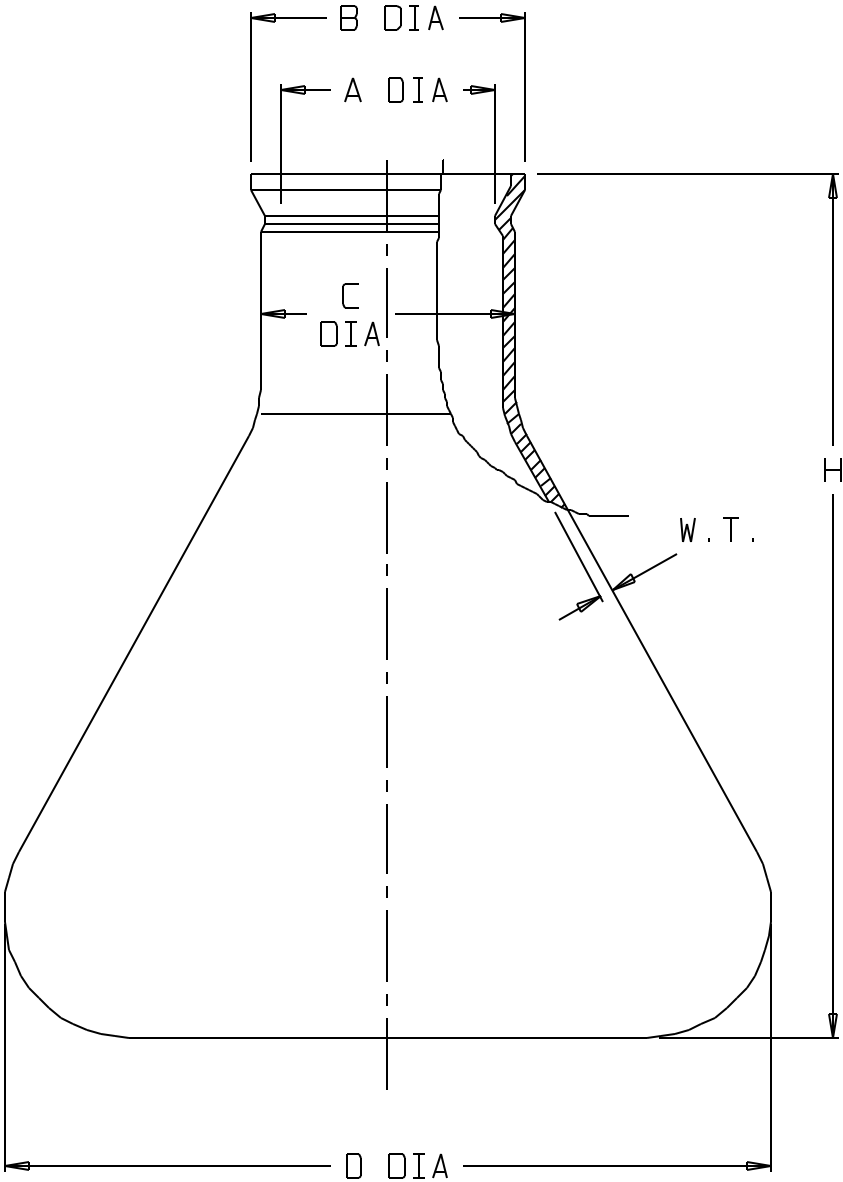

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher  
SCIENTIFIC

Thermo Fisher Scientific  
75 Panorama Creek Drive  
Rochester, NY 14625-2385, USA

MADE

CARNEY

APP'D

PVC

CK'D

PVC

3/11/96

PSS 00-4105-2800

REV.

0396

DESCRIPTION:

FERNBACH CULTURE FLASK