


CARBOY MATERIAL	PP	
CLOSURE MATERIAL	WHITE PP	
SIZE (NOMINAL VOLUME L/GAL)	20/5	
NOMINAL BRIM CAPACITY	22.5	
NECK FINISH (mm)	83B	
THREAD TPI	2	
NOMINAL WEIGHT W/CLOSURE (grams)	2800	
	INCHES	MM (REF)
A (NECK ID)	2.52±.10	64.0
B (HEIGHT WITH CLOSURE)	20.9±.3	531
C (HEIGHT WITHOUT CLOSURE)	20.4±.2	518
D (DIAMETER)	11.2±.2	284
E (MINIMUM WALL THICKNESS)	.150	3.81

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

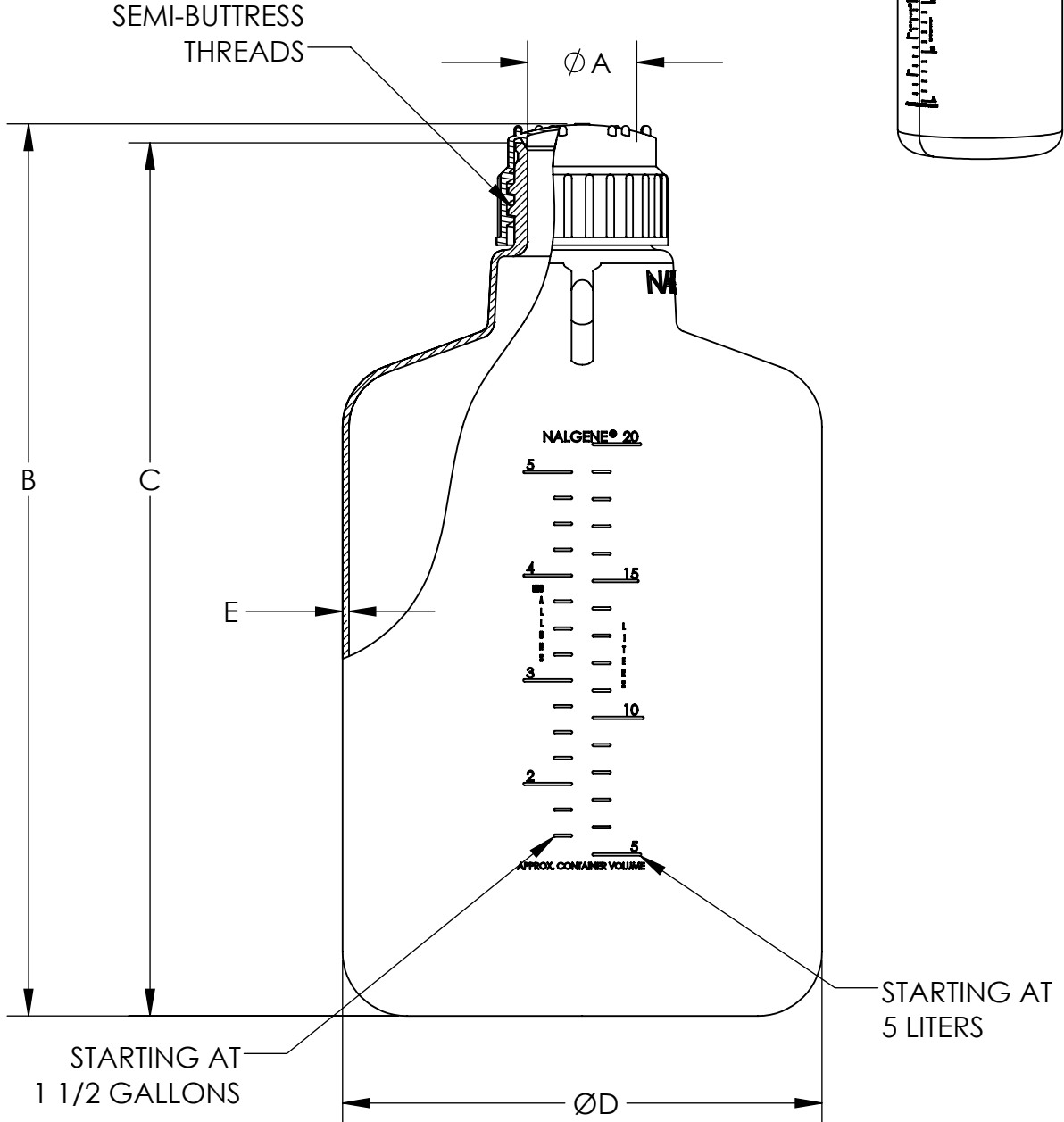

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	APP'D	PSS 2226-0050	REV. 0416
P. PELYCHATY	4/28/16		
CK'D JC	PWC		
DESCRIPTION: 20L CARBOY, ROUND WITH HANDLES			